


POFMP

## Push-On Fittings

### POFMP Series

Male Pipe x Push-On Barb

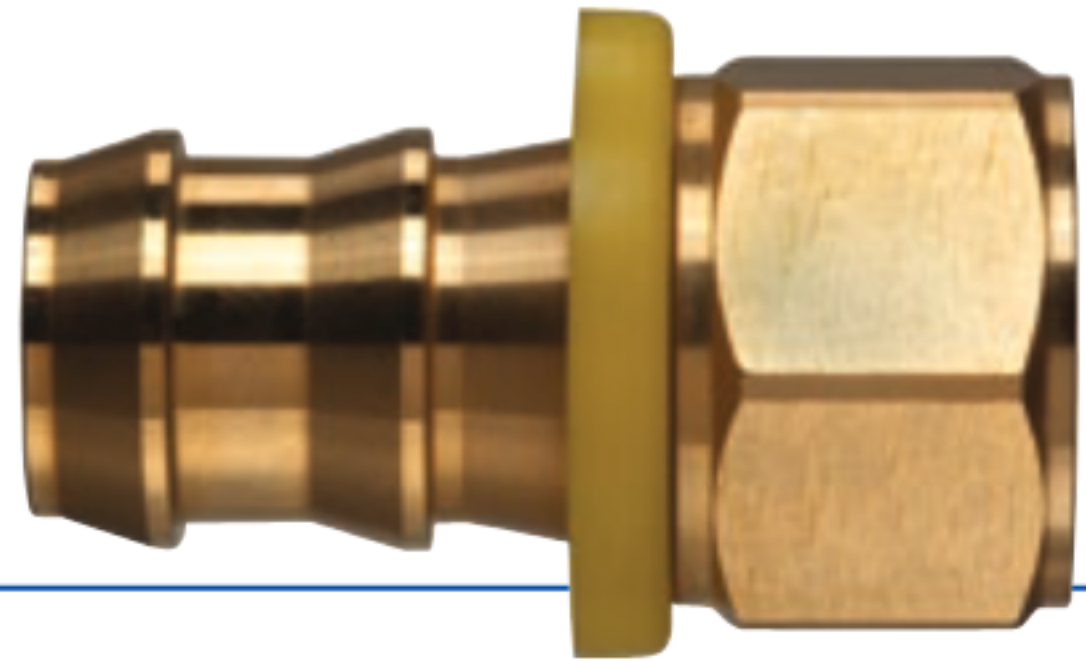

POFFP

### POFFP Series

Female Pipe x Push-On Barb

**VIEW ONLINE**



SCAN FOR INFO  
or visit  
[KOA.link/  
POFMP-POFFP](http://KOA.link/POFMP-POFFP)

#### FEATURES AND ADVANTAGES

- Couplings designed specifically for use with push-on type hoses.
- Push-On fittings will lock on the hose without the use of clamps or ferrules.
- Applications include low-pressure air, fuel, water, oil, and lubrication lines.

#### MATERIAL SPECIFICATIONS

- Brass – ASTM B124, Grade C37700.

Part Number	Size (in)	Fitting Size (in)	Thread Type	Thread (in-TPI)	PSI Rating at 70°F	Weight Each (lbs)	Standard Carton
POFMP-0402	1/4	1/8	NPTF	1/8 - 27	150	0.031	100
POFMP-0404	1/4	1/4	NPTF	1/4 - 18	150	0.044	100
POFMP-0406	1/4	3/8	NPTF	1/4 - 18	150	0.055	50
POFMP-0604	3/8	1/4	NPTF	1/4 - 18	150	0.053	50
POFMP-0606	3/8	3/8	NPTF	3/8 - 18	150	0.071	50
POFMP-0608	3/8	1/2	NPTF	1/2 - 14	150	0.119	25
POFMP-0808	1/2	1/2	NPTF	1/2 - 14	150	0.121	25
POFMP-1008	5/8	1/2	NPTF	1/2 - 14	150	0.143	25
POFMP-1012	5/8	3/4	NPTF	3/4 - 14	150	0.190	25
POFMP-1208	3/4	1/2	NPTF	1/2 - 14	150	1.960	25
POFMP-1212	3/4	3/4	NPTF	3/4 - 14	150	1.940	25

Part Number	Size (in)	Fitting Size (in)	Thread Type	Thread (in-TPI)	PSI Rating at 70°F	Weight Each (lbs)	Standard Carton
POFFP-0402	1/4	1/8	NPTF	1/8 - 27	150	0.029	100
POFFP-0404	1/4	1/4	NPTF	1/4 - 18	150	0.049	100
POFFP-0604	3/8	1/4	NPTF	1/4 - 18	150	0.055	50
POFFP-0606	3/8	3/8	NPTF	3/8 - 18	150	0.064	50
POFFP-0806	1/2	3/8	NPTF	3/8 - 18	150	0.077	50
POFFP-0808	1/2	1/2	NPTF	1/2 - 14	150	0.099	25
POFFP-1008	5/8	1/2	NPTF	1/2 - 14	150	0.119	25
POFFP-1212	3/4	3/4	NPTF	3/4 - 14	150	0.234	25

Because we continually examine ways to improve our products, we reserve the right to alter specifications or discontinue products without prior notice.