

KC3-H83 Series



NEW

DESCRIPTION

With a new intuitive MACH interface including USB crimp library support and additional improvements all-around, this crimper greatly increases crimping efficiency.

View Up To Date Info



◀ SCAN OR VISIT
[KOA.link/
KC3-H83](http://KOA.link/KC3-H83)

CONTROL MECHANISM **NEW**



MACH

- Full-color, touch-screen display
- Stores up to 1000 crimp specifications
- Built-in crimp diameter calculator
- Adjustable reopen diameter
- USB port option for data transfer
- Industrial hose crimp calculator

INCLUDED ACCESSORIES



Electric Foot Pedal
PEDAL-ES



Crimp Calculator



Die Segment
Change Tool

OPTIONAL ACCESSORIES (PGS. 41 – 48)



Back Limit Switch



Quick Change
Die Tool
KCQCT-H69



Production Quick
Change Die Tool
KCPQCT-H69




Die Holder Base
(12 pc.)
DIEBASE-H69



Die Rack (12 pc.)
DIERACK-H69



Custom Made Dies

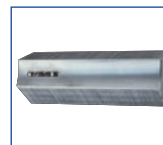

Marking Dies

Hose Capacity (in)		Crimping Force (ton)
1 – 2 Wire	1 1/2	150
4 SP / 6 SP	1 1/4 / 1	
90° Fittings	1 1/4	
Industrial	1 1/2	

Opening Diameter	
Max. Without Dies (mm / in)	111 / 4.37
Max. With Dies (mm / in)	96 / 3.78
By Die Size (mm / in)	Die Size + 42 / 1.65

Crimper Size	
L x W x H (in)	27.2 x 24.3 x 29.9
Weight (lbs)	485

Part Number	Motor Info
KC3-H83-230/1	5.0 HP (230 V) 1 PH
KC3-H83-230/3	5.0 HP (230 V) 3 PH

Hydraulic Fluid	
Type	ISO 46
Amount	70L = 18.50 Gal.

Die Series	Die Range (mm)
H69	6 – 54

Die Number	Crimp Range (mm)	Closed Diameter (mm)	Length (mm)	Weight (lbs/ea)
KCDH69-6	6.0 - 8.0	6	60	4.0
KCDH69-8	8.0 - 10.0	8	60	4.0
KCDH69-10	10.0 - 12.0	10	60	4.0
KCDH69-12	12.0 - 14.0	12	60	4.0
KCDH69-14	14.0 - 16.0	14	60	4.0
KCDH69-16	16.0 - 19.0	16	60	4.0
KCDH69-19	19.0 - 22.0	19	60	4.0
KCDH69-22	22.0 - 25.0	22	60	4.0
KCDH69-25	25.0 - 29.0	25	60	4.0
KCDH69-29	29.0 - 34.0	29	70	4.0
KCDH69-34	34.0 - 38.0	34	70	4.0
KCDH69-38	38.0 - 42.0	38	85	4.0
KCDH69-42	42.0 - 46.0	42	85	4.0
KCDH69-46	46.0 - 50.0	46	85	4.0
KCDH69-50	50.0 - 54.0	50	85	4.0
KCDH69-54	54.0 - 58.0	54	75	4.0

Because we continually examine ways to improve our products, we reserve the right to alter specifications or discontinue products without prior notice.