

## KCS-TF1/E Series



Hose Capacity (in)		Motor Strength (HP)
1 – 2 Wire	1 1/4	<b>1.5</b>
4 SP / 6 SP	1 1/4 / 1	
Industrial	2	
Max opening (mm)	58	

Cutter Size	
L x W x H (in)	20.7 x 26.0 x 17.5
Weight (lbs)	66.1
Blade Diameter (mm)	250


Part Number	Motor Info
KCS-TF1/E-110/1	1.5 HP (110 V) 1 PH
KCS-TF1/E-12V	1.5 HP (12 V)

### DESCRIPTION

A compact, bench mounted unit ideal for cutting 1 1/4" four spiral and 1" six spiral hydraulic hose.

Suggested for pairing with KC1-H83 and KC3-H88 series crimpers.

### INCLUDED ACCESSORIES

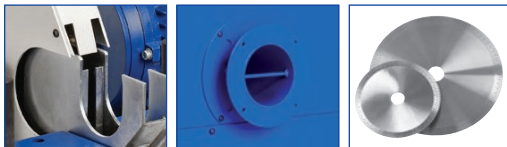

Recessed Blade

Ventilation Port\*

Serrated Blade†  
BLADE-SER250

\* Separate suction device required for fume extraction


† CAUTION: The included Serrated Blade is not recommended for use with hoses with a steel cover and/or containing steel helical reinforcement.

View Up To Date Info



← SCAN OR VISIT  
[KOA.link/  
KCS-TF1-E](https://KOA.link/KCS-TF1-E)

### OPTIONAL ACCESSORIES

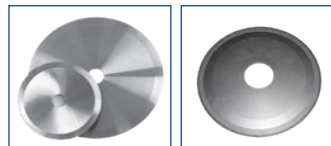

Smooth Blade  
BLADE-SMT250

Diamond Blade  
BLADE-DIA250

Because we continually examine ways to improve our products, we reserve the right to alter specifications or discontinue products without prior notice.