

KCS-TF4 Series



**Low
Smoke**

Hose Capacity (in)		Motor Strength (HP)
1 – 2 Wire	3	7.5
4 SP / 6 SP	2 1/2 / 2	
Industrial	3	
Max opening (mm)	100	

Cutter Size	
L x W x H (in)	44.0 x 23.8 x 57.2
Weight (lbs)	717
Blade Diameter (mm)	400

Part Number	Motor Info
KCS-TF4-230/3	7.5 HP (230 V) 3 PH

DESCRIPTION

Cuts up to 2" six spiral hoses. Blade chamber is completely recessed in the body of the unit allowing for more efficient ventilation. Uses 100 PSI pneumatic input.

Suggested for use with KC4-V150 and KC4-V159 series crimpers.

View Up To Date Info



◀ SCAN OR VISIT


KOA.link/

KCS-TF4-2303

INCLUDED ACCESSORIES



Recessed Blade Chamber

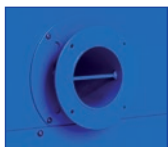


Ventilation Port*



Pneumatic Foot Pedal



Stroke Counter

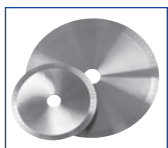


Serrated Blade†
BLADE-SER250

OPTIONAL ACCESSORIES



Centering & Measuring Device
CENTER-KCS

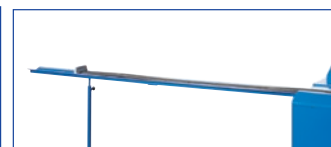


Measuring Hose Tray
TRAY-KCS



Blowing Kit
BLKIT-KCS45



Fume Extractor
FUME-KCS4

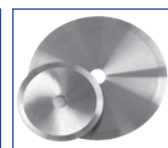

Smooth Blade
BLADE-SMT250



Diamond Blade
BLADE-DIA250

* Separate suction device required for fume extraction

† CAUTION: The included Serrated Blade is not recommended for use with hoses with a steel cover and/or containing steel helical reinforcement

Because we continually examine ways to improve our products, we reserve the right to alter specifications or discontinue products without prior notice.