


KC1-H47PM Series

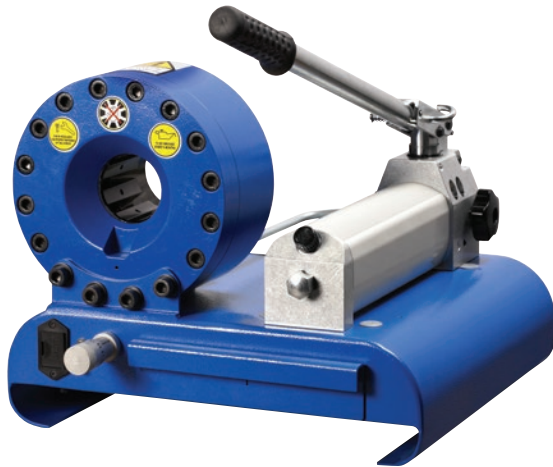

DESCRIPTION

Looking for a reliable crimping machine that won't take up a lot of space? With its small footprint the KC1-H47PM is a perfect fit for crowded shops. Its small size also makes it suitable for quick trips into the field.

View Up To Date Info



◀ SCAN OR VISIT
[KOA.link/
KC1-H47PM](https://KOA.link/KC1-H47PM)

INCLUDED ACCESSORIES



Die Segment
Change Tool
KCDCT-H39



Hand Pump



Die Storage Drawer

OPTIONAL ACCESSORIES (PGS. 41 – 48)



Case and Dies
KC1-H47E-DIECASE



Custom Made Dies

Hose Capacity (in)		Crimping Force (ton)
1 – 2 Wire	1	110
4 SP / 6 SP	NA	
90° Fittings	3/8	
Industrial	NA	

Opening Diameter	
Max. With Dies (mm / in)	49 / 1.93
By Die Size (mm / in)	Die Size + 20 / 0.79

Crimper Size	
L x W x H (in)	15.4 x 20.7 x 11.8
Weight (lbs)	71

Part Number	Pump Info
KC1-H47PM	Hand

CONTROL MECHANISM



Dial micrometer, with electric limit switch indicating when the crimp diameter is reached.

Die Series	Die Range (mm)
H39	6 – 29

Die Number	Crimp Range (mm)	Closed Diameter (mm)	Length (mm)	Weight (lbs/ea)
KCDH39-6	6.0 - 8.0	6	55	4.0
KCDH39-8	8.0 - 10.0	8	55	4.0
KCDH39-10	10.0 - 12.0	10	55	4.0
KCDH39-12	12.0 - 14.0	12	55	4.0
KCDH39-14	14.0 - 16.0	14	55	4.0
KCDH39-16	16.0 - 19.0	16	55	4.0
KCDH39-19	19.0 - 22.0	19	55	4.0
KCDH39-22	22.0 - 25.0	22	55	4.0
KCDH39-25	25.0 - 29.0	25	65	4.0
KCDH39-29	29.0 - 34.0	29	65	4.0

Because we continually examine ways to improve our products, we reserve the right to alter specifications or discontinue products without prior notice.