

# KCS-TF4/E Series



Hose Capacity (in)		Motor Strength (HP)
1 – 2 Wire	3	<b>5.5</b>
4 SP / 6 SP	3 / 2	
Industrial	4	
Max opening (mm)	130	

Cutter Size	
L x W x H (in)	45.3 x 26.0 x 26.3
Weight (lbs)	187.4
Blade Diameter (mm)	400

Part Number	Motor Info
KCS-TF4/E-230/1	5.5 HP (230 V) 1 PH

## DESCRIPTION

Ideal for industrial hoses, cutting up to 4" ID. Can be placed on the ground, eliminating the need to lift heavy hoses.

Diamond blade included in order to cut through heavy walled hoses or ones with steel helical reinforcement.

Ideal for use with KC3-H144 or KC3-H170 series crimpers.

[View Up To Date Info](#)



◀ SCAN OR VISIT


[KOA.link/](https://KOA.link/)

**KCS-TF4-E-2301**


## INCLUDED ACCESSORIES



Recessed Blade

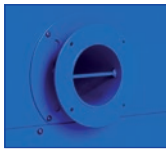


Ventilation Port\*

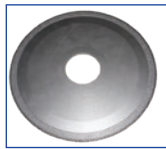


Diamond Blade  
BLADE-DIA250

\* Separate suction device required for fume extraction


## OPTIONAL ACCESSORIES

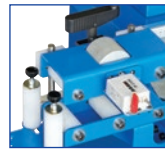

Centering &  
Measuring Device  
CENTER-KCS

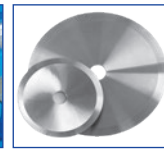

Smooth Blade  
BLADE-SMT250

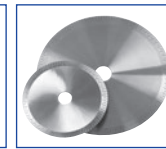

Serrated Blade†  
BLADE-SER250

† CAUTION: The included Serrated Blade is not recommended for use with hoses with a steel cover and/or containing steel helical reinforcement.

Because we continually examine ways to improve our products, we reserve the right to alter specifications or discontinue products without prior notice.