


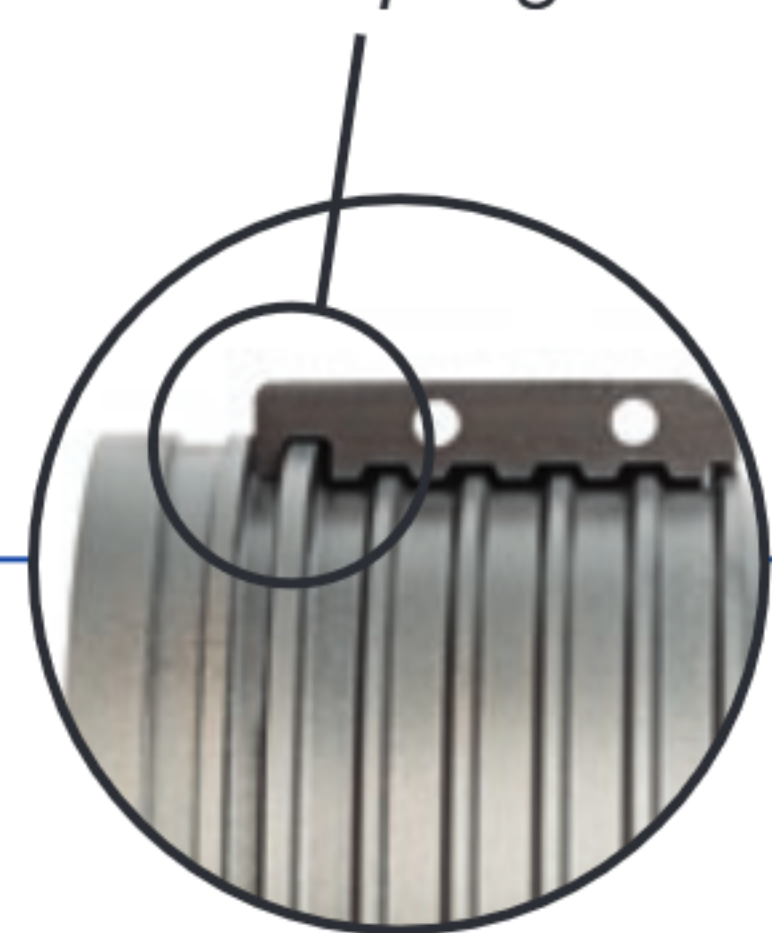

Don't risk a leak!
Unique Locking Lip™ design
increases coupling retention.



AL-LDHC Series Oilfield Hose Coupling

- Lightweight aluminum with abrasion resistant anodized hard coating
- Multiple collar segments evenly distribute pressure on the hose for even sealing
- Locking Lip™ provides better coupling retention than other designs

View Up To Date Info



◀ SCAN OR VISIT
[KOA.link/
AL-LDHC](https://KOA.link/AL-LDHC)

| Part Number | Size (in) | Working Pressure (psi) at 68°F | Burst Pressure (psi) at 68°F | Weight Each (lbs) | Standard Carton |
|-------------|-----------|--------------------------------|------------------------------|-------------------|-----------------|
| AL-LDHC1000 | 10 | 200 | 600 | 41.20 | 1 |
| AL-LDHC1200 | 12 | 200 | 600 | 57.30 | 1 |



GEC-B Series Grooved Couplings

- For use with AL-LDHC coupling or grooved end pipe
- Durable ductile iron
- UL listed
- Buna (nitrile) gasket included

View Up To Date Info



◀ SCAN OR VISIT
[KOA.link/
GEC](https://KOA.link/GEC)

| Part Number | Size (in) | Weight Each (lbs) | Standard Carton |
|-------------|-----------|-------------------|-----------------|
| GEC-B1000 | 10 | 26.15 | 1 |
| GEC-B1200 | 12 | 30.65 | 1 |



GEG-BUNA Series Grooved Gasket

- Fits GEC-B Series couplings
- Buna (nitrile) material, resistant to oil, gas, and moderately aggressive chemicals

View Up To Date Info



◀ SCAN OR VISIT
[KOA.link/
GEG](https://KOA.link/GEG)

| Part Number | Size (in) | Weight Each (lbs) | Standard Carton |
|--------------|-----------|-------------------|-----------------|
| GEG-BUNA1000 | 10 | 0.771 | 1 |
| GEG-BUNA1200 | 12 | 0.889 | 1 |

Because we continually examine ways to improve our products, we reserve the right to alter specifications or discontinue products without prior notice.